


GW25

Shaft block

Shaft block

Technical information

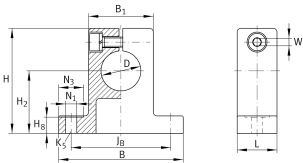

Your current product variant

Size code 25

Main Dimensions & Performance Data

D	25 mm	Diameter
B	74 mm	Width
L	25 mm	Length
H	58 mm	Height
≈m	0,26 kg	Weight

Mounting dimensions

J B	60 mm	Mounting Dimension
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	38 mm	Mounting Dimension
H 2	35 mm	Mounting Dimension
Tol H 2	+ 0,15 mm	Upper tolerance
Tol H 2	- 0,15 mm	Lower tolerance
H 8	8,5 mm	Mounting Dimension
N 1	5,5 mm	Mounting Dimension
N 3	11 mm	Mounting Dimension
K 5	M5	Size thread fixing screws above
W	4 mm	Width Across Flat