


PAGBA40-PP-AS

Linear plain bearing and housing unit

Linear plain bearing and housing unit; sealed on all sides, with relubrication facility

Technical information

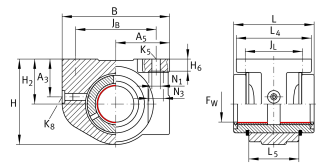

Your current product variant

Size code	40
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

F _W	40 mm	Diameter of ball complement
H	87 mm	Height
L	80 mm	Length
Tol L	h12	Tolerance
B	108 mm	Width
≈m	1,09 kg	Weight



Mounting dimensions

J _B	86 mm	
Tol J _B	+ 0,2 mm	Upper tolerance
Tol J _B	- 0,2 mm	Lower tolerance
A ₅	54 mm	
Tol A ₅	+ 0,015 mm	Upper tolerance
Tol A ₅	- 0,015 mm	Lower tolerance
L ₄	78 mm	
L ₅	56 mm	
J _L	58 mm	
Tol J _L	+ 0,2 mm	Upper tolerance
Tol J _L	- 0,2 mm	Lower tolerance
H ₂	45 mm	Center height
Tol H ₂	+ 0,01 mm	Upper tolerance
Tol H ₂	- 0,01 mm	Lower tolerance
A ₃	30 mm	
H ₆	11 mm	
Tol H ₆	- 0,5 mm	Tolerance
N ₁	9,2 mm	
N ₃	15 mm	
K ₅	M8	
K ₈	NIPA2	Lubrication nipple