


GW10

Shaft block

Shaft block

Technical information

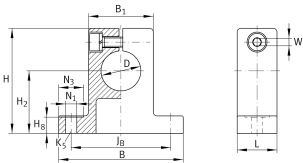

Your current product variant

Size code 10

Main Dimensions & Performance Data

D	10 mm	Diameter
B	37 mm	Width
L	11 mm	Length
H	30 mm	Height
≈m	30 g	Weight

Mounting dimensions

J _B	28 mm	Mounting Dimension
Tol J _B	+ 0,15 mm	Upper tolerance
Tol J _B	- 0,15 mm	Lower tolerance
B ₁	18 mm	Mounting Dimension
H ₂	17 mm	Mounting Dimension
Tol H ₂	+ 0,15 mm	Upper tolerance
Tol H ₂	- 0,15 mm	Lower tolerance
H ₈	5 mm	Mounting Dimension
N ₁	3,4 mm	Mounting Dimension
N ₃	8 mm	Mounting Dimension
K ₅	M3	Size thread fixing screws above
W	2,5 mm	Width Across Flat