


GW40

Shaft block

Shaft block

Technical information

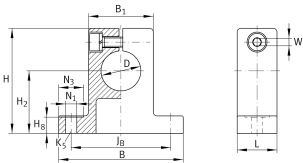

Your current product variant

Size code 40

Main Dimensions & Performance Data

D	40 mm	Diameter
B	108 mm	Width
L	32 mm	Length
H	86 mm	Height
≈m	0,67 kg	Weight

Mounting dimensions

J B	86 mm	Mounting Dimension
Tol J B	+ 0,2 mm	Upper tolerance
Tol J B	- 0,2 mm	Lower tolerance
B 1	56 mm	Mounting Dimension
H 2	50 mm	Mounting Dimension
Tol H 2	+ 0,15 mm	Upper tolerance
Tol H 2	- 0,15 mm	Lower tolerance
H 8	12 mm	Mounting Dimension
N 1	9,1 mm	Mounting Dimension
N 3	18 mm	Mounting Dimension
K 5	M8	Size thread fixing screws above
W	6 mm	Width Across Flat