
**GW12**

Shaft block

Shaft block

Technical information

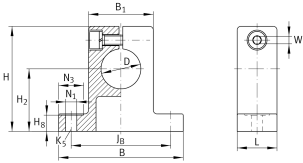

Your current product variant

Size code	12
-----------	----

Main Dimensions & Performance Data

D	12 mm	Diameter
B	42 mm	Width
L	12 mm	Length
H	35 mm	Height
≈m	40 g	Weight

Mounting dimensions

J B	32 mm	Mounting Dimension
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	20 mm	Mounting Dimension
H 2	20 mm	Mounting Dimension
Tol H 2	+ 0,15 mm	Upper tolerance
Tol H 2	- 0,15 mm	Lower tolerance
H 8	5,5 mm	Mounting Dimension
N 1	4,5 mm	Mounting Dimension
N 3	10 mm	Mounting Dimension
K 5	M4	Size thread fixing screws above
W	3 mm	Width Across Flat