




View product details on medias

05.09.2026, 16:09:21 UTC


SCHAEFFLER

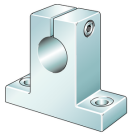

GWA20

Shaft block

Technical information

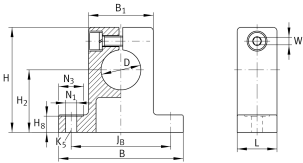

Your current product variant

Size code 20

Main Dimensions & Performance Data

D	20 mm	Diameter
B	60 mm	Width
L	20 mm	Length
H	50 mm	Height
≈m	0,15 kg	Weight

Mounting dimensions

J B	45 mm	Mounting Dimension
Tol J B	+ 0,15 mm	Upper tolerance
Tol J B	- 0,15 mm	Lower tolerance
B 1	32 mm	Mounting Dimension
H 2	30 mm	Mounting Dimension
Tol H 2	+ 0,15 mm	Upper tolerance
Tol H 2	- 0,15 mm	Lower Tolerance
H 8	7,5 mm	Mounting Dimension
N 1	5,5 mm	Mounting Dimension
N 3	11 mm	Mounting Dimension
K 5	M5	Size thread fixing screws above
W	3 mm	Width across flats

The data sheet only contains an overview of the technical data of the selected product. Please refer to the additional documentation for this product. For further information, please use the following link on our website: [Contact form](#)