


**PAB12-PP-AS**

Linear plain bearing

Linear plain bearing; sealed on all sides, with relubrication facility

Technical information

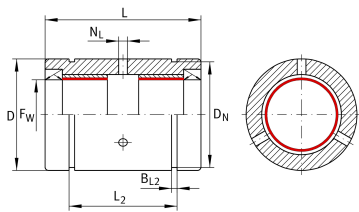

Your current product variant

Size code	12
Seal	PP
Relubrication	AS

Main Dimensions & Performance Data

$F_{W\text{}}$	12 mm	Diameter of ball complement
D	22 mm	Outer diameter
Tol D	h7	Tolerance
L	32 mm	Length
Tol L	h12	Tolerance
C_0	60.000 N	Load capacity stat. C_0
$\approx m$	26 g	Weight

Mounting dimensions

L_2	22,6 mm	Mounting Dimension
Tol L_2	H13	Tolerance
B_{L2}	1,3 mm	
Tol B_{L2}	H13	Tolerance
D_N	21 mm	
N_L	2,5 mm	
Tol N_L	H13	Tolerance