



**KSO50-PP**

Linear Ball Bearing

Linear ball bearings KSO...-PP, heavy load range, lip seals on both sides

Technical information

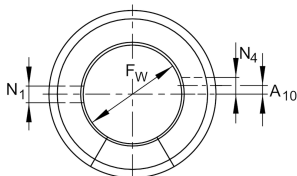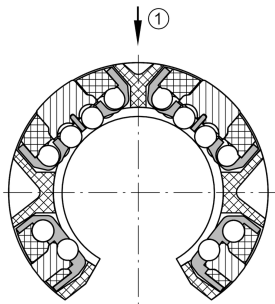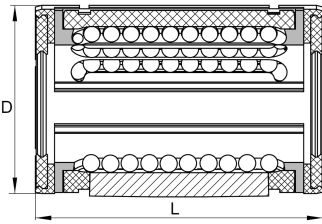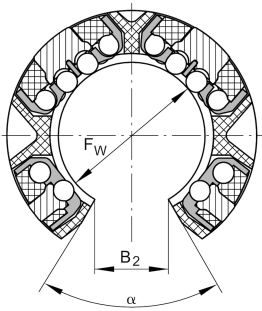

KS30, 40, 50
KSO30, 40, 50

Your current product variant

Size code	50	
Seal	PP	Sealed

Main Dimensions & Performance Data

F_w	50 mm	Bore diameter
D	75 mm	Outside diameter
L	100 mm	Length
C_{max}	15.100 N	Load capacity dyn.
$C_{0 max}$	13.900 N	Load capacity stat.
m	0,47 kg	Weight

Mounting dimensions

B 2	22,7 mm	Width of sector opening
A 10	2,5 mm	Angle of sector opening
N 1	4,5 mm	
N 4	5 mm	
α	54 °	Angle of sector opening
	6	Number of rows balls



View product details on medias

07.08.2026, 03:46:32 UTC

SCHAEFFLER

