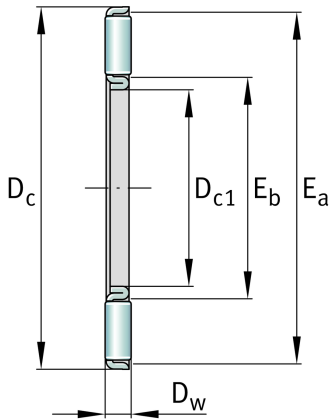
**AXK4565-A** **Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	45 mm	Bore diameter cage
D_c	65 mm	Outside diameter
D_w	3 mm	Rolling element diameter
E_a	63 mm	Raceway dimension
E_b	50 mm	Raceway dimension
c_a	30.000 N	Basic dynamic load rating, axial
c_{0a}	128.000 N	Basic static load rating, axial
c_{ua}	13.600 N	Fatigue load limit, axial
n_G	5.200 1/min	Limiting speed
n_{gr}	2.170 1/min	Reference speed
$\approx m$	18,105 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS4565

Axial bearing washer