



**PCJ60-XL-N**

Flanged housing unit

Housing units PCJ, four-bolt flanged housing units, cast iron, eccentric locking collar, P seals

X-life

Technical information

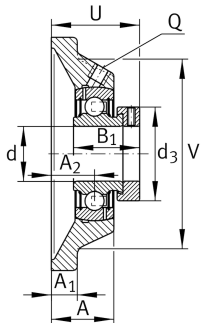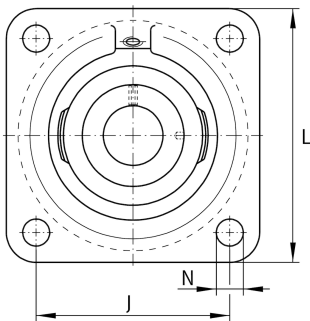

Your current product variant

Groove	N	Cast iron housing with undercut slot for end caps
Material	GG	Grey cast iron

Main Dimensions & Performance Data

d	60 mm	Bore diameter
L	175 mm	Flange width
U	73,6 mm	Total height unit
C _r	56.000 N	Basic dynamic load rating, radial
C _{0r}	36.000 N	Basic static load rating, radial
C _{ur}	1.710 N	Fatigue load limit, radial
≈m	3,859 kg	Weight

Mounting dimensions

J	143 mm	Distance fixing bore
N	18 mm	Fixing bore
n	4	Number of screwing holes



Dimensions

A	47,5 mm	Height housing
A ₁	16 mm	Thickness of flange
A ₂	34 mm	Distance raceway
V	150 mm	Shoulder diameter housing
Q	M6	Connection thread for lubrication
d ₃	84 mm	Outside diameter locking device

Additional information

1	Number of housings
CJ12	Housing
GRAE60-XL-NPP-B	Bearing designation
KASK12	Protecting cap

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.