
**204-XL-KRR**

Deep groove ball bearing

Radial insert ball bearings 2..-KRR, cylindrical outer ring, inner ring for fit, R seals on both sides

X-life

Technical information

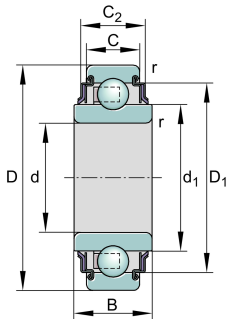

Your current product variant

Sealing	KRR	Lip seals on both sides
---------	-----	-------------------------

Main Dimensions & Performance Data

d	20 mm	Bore diameter
D	47 mm	Outside diameter
B	17,7 mm	Width
C _r	13.600 N	Basic dynamic load rating, radial
C _{0r}	6.600 N	Basic static load rating, radial
≈m	0,11 kg	Weight

Dimensions

D ₁	38,7 mm	Outside diameter seal
C	14 mm	Width, outer ring
C ₂	14 mm	Sealing total width
d ₁	28,4 mm	Rib diameter inner ring
r _{min}	1 mm	Minimum chamfer dimension

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	100 °C	Operating temperature max.



Calculation factors

f_0	13,1	Calculation factor
-------	------	--------------------

Characteristics

-  Radial load
-  Axial load in one direction
-  Axial load in two directions
-  Lifetime lubrication, freedom from maintenance
-  Grease Lubrication
-  Sealed on both sides