

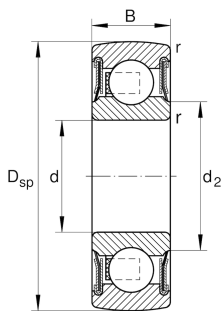
IMAGE
COMING SOON**204-XL-NPP-B**

Self-aligning deep groove ball bearings

Self-aligning deep groove ball bearings 2...-
NPP-B, spherical outer ring, inner ring for fit,
R seals on both sides

X-life

Technical information

**Your current product variant**

Type of Seal	NPP	
Shape of outer surface	B	Spherical

Main Dimensions & Performance Data

d	20 mm	Bore diameter
D _{SP}	47 mm	Outside diameter
B	14 mm	Width
C _r	13.600 N	Basic dynamic load rating, radial
C _{0r}	6.600 N	Basic static load rating, radial
≈m	0,09 kg	Weight

Dimensions

d ₂	26,5 mm	Rib diameter sealing inner ring
r _{min}	1 mm	Minimum chamfer dimension

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Calculation factors

f ₀	13,1	Calculation factor
----------------	------	--------------------



Characteristics



Radial load



Axial load in one direction



Axial load in two directions



Lifetime lubrication, freedom from maintenance



Grease Lubrication



Sealed on both sides



Static angular error and misalignment