




GSH35-XL-2RSR-B

Radial insert ball bearing

Radial insert ball bearings GSH...2RSR-B, spherical outer ring, location by adapter sleeve, RSR seals on both sides

X-life

Technical information

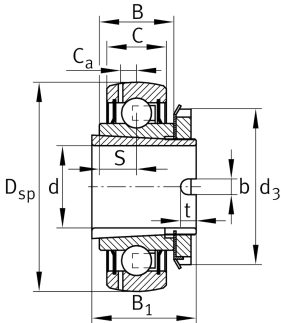

Main Dimensions & Performance Data

D _{SP}	72 mm	Outside diameter
B	19 mm	Width
C _{0r}	15.300 N	Basic static load rating, radial
C _{ur}	820 N	Fatigue load limit, radial
C _r	24.900 N	Basic dynamic load rating, radial
≈m	0,4 kg	Weight

Dimensions

C	19 mm	Width, outer ring
S	9,5 mm	Distance raceway
C _a	5,8 mm	Distance to lubrication hole
b	5 mm	Width retaining slot
t	5 mm	Hight retaining slot adapter sleeve
d ₃	52 mm	Outside diameter locking collar/locknut

Calculation factors

f ₀	13,9	Calculation factor
----------------	------	--------------------

Additional information

HUESH.SH35- ZN-0100-HLA	Adapter sleeve
----------------------------	----------------



Characteristics

-  Radial load
-  Axial load in one direction
-  Axial load in two directions
-  Lifetime lubrication, freedom from maintenance
-  Grease Lubrication
-  Sealed on both sides
-  Static angular error and misalignment