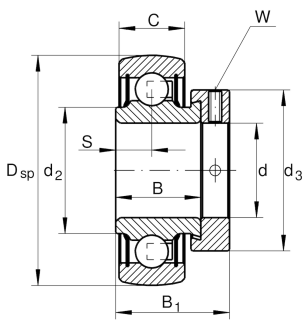
**RALE20-XL-NPP-B**

Radial insert ball bearing

Radial insert ball bearings RALE...NPP-B, spherical outer ring, location by eccentric locking collar, P seals on both sides

X-life

Technical information

**Main Dimensions & Performance Data**

d	20 mm	Bore diameter
D _{SP}	42 mm	Outside diameter
B	16,7 mm	Width
C _{0r}	5.000 N	Basic static load rating, radial
C _{ur}	238 N	Fatigue load limit, radial
B ₁	24,5 mm	Locking collar total width
C _r	9.400 N	Basic dynamic load rating, radial
≈m	0,1 kg	Weight

Dimensions

C	12 mm	Width, outer ring
S	6 mm	Distance raceway
d ₂	25,4 mm	Rib diameter sealing inner ring
d ₃	30 mm	Outside diameter locking collar/locknut
W	2,5 mm	Width of flats

Calculation factors

f ₀	13,8	Calculation factor
----------------	------	--------------------



Characteristics



Radial load



Axial load in one direction



Axial load in two directions



Lifetime lubrication, freedom from maintenance



Grease Lubrication



Sealed on both sides



Static angular error and misalignment