
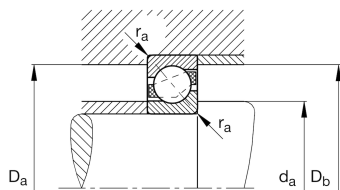


**FAG****X-life****7302-B-XL-TVP** [🔗](#)

Angular contact ball bearing

Angular contact ball bearing 73...-B-XL-TVP,
single row, X-life, plastic cage

Technical information

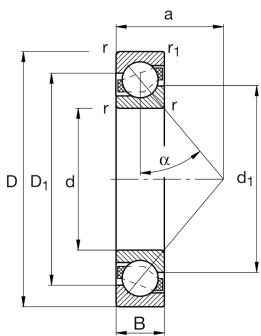

Your current product variant

Design variant	B	B
Type of Seal	Without	Not sealed
Cage	TVP	Solid cage made of glass-fiber reinforced polyamid PA66
Tolerance class	P6	Class 6 (ISO 492:2023)
Dimensional / heat stabilization	S0	Rings dimensional stabilized up to 150°
Lubricant	Without	Bearing not greased

Main Dimensions & Performance Data

d	15 mm	Bore diameter
D	42 mm	Outside diameter
B	13 mm	Width
C _r	15.100 N	Basic dynamic load rating, radial
C _{0r}	7.200 N	Basic static load rating, radial
C _{ur}	495 N	Fatigue load limit, radial
n _G	24.400 1/min	Limiting speed
n _{gr}	14.200 1/min	Reference speed
≈m	0,082 kg	Weight



Mounting dimensions

$d_{a\min}$	20,6 mm	Minimum diameter of shaft shoulder
$D_{a\max}$	36,4 mm	Maximum diameter of housing shoulder
$D_{b\max}$	37,8 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1 mm	Maximum fillet radius of shaft
$r_{a1\max}$	0,6 mm	Maximum fillet radius of housing

Dimensions

$r_{\min}$	1 mm	Minimum chamfer dimension
$r_{1\min}$	0,6 mm	Minimum chamfer dimension
D_1	31,65 mm	Shoulder diameter on outer ring wide side face
d_1	25,99 mm	Shoulder diameter on inner ring wide side face
a	18,5 mm	Distance between the apexes of the pressure cones
α	40 °	Contact angle

Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.

Characteristics

	Radial load
	Axial load in one direction
	Grease Lubrication
	Oil Lubrication
	Not sealed