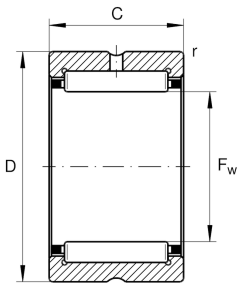
**NK50/25-TV-XL** [🔗](#)

Needle roller bearing

Needle roller bearings NK, light series

X-life

Technical information

**Your current product variant**

Lubricant	Without	
Cage	TV	Plastic Cage made from PA66
Cage feature	Standard	
Tolerance class	PN	Normal (DIN 620-2)

Main Dimensions & Performance Data

F_w	50 mm	Under roller diameter
D	62 mm	Outside diameter
C	25 mm	Width, outer ring
C_r	48.500 N	Basic dynamic load rating, radial
C_{0r}	87.000 N	Basic static load rating, radial
C_{ur}	15.000 N	Fatigue load limit, radial
n_G	9.200 1/min	Limiting speed
n_{gr}	5.400 1/min	Reference speed
$\approx m$	145 g	Weight

Dimensions

r_{min}	0,6 mm	Minimum chamfer dimension
-----------	--------	---------------------------



Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Additional information

G50X62X5	Sealing ring
SD50X62X5	Sealing ring 2

Characteristics

-  Radial load
-  Grease Lubrication
-  Oil Lubrication
-  Not sealed
-  Small design envelope