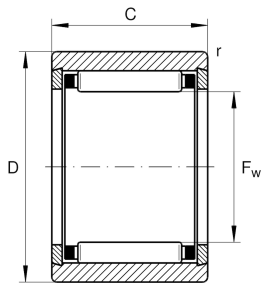
**NK8/16-TV-XL**

Needle roller bearing

Needle roller bearings NK, light series

X-life

Technical information

**Your current product variant**

Lubricant	Without	
Cage	TV	Plastic Cage made from PA66
Cage feature	Standard	
Tolerance class	PN	Normal (DIN 620-2)

Main Dimensions & Performance Data

F_w	8 mm	Under roller diameter
D	15 mm	Outside diameter
C	16 mm	Width, outer ring
C_r	5.800 N	Basic dynamic load rating, radial
C_{0r}	5.800 N	Basic static load rating, radial
C_{ur}	990 N	Fatigue load limit, radial
n_G	32.500 1/min	Limiting speed
n_{gr}	36.500 1/min	Reference speed
$\approx m$	11,7 g	Weight

Dimensions

r_{min}	0,3 mm	Minimum chamfer dimension
-----------	--------	---------------------------



Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Additional information

G8X15X3	Sealing ring
SD8X15X3	Sealing ring 2

Characteristics

-  Radial load
-  Grease Lubrication
-  Oil Lubrication
-  Not sealed
-  Small design envelope