
**NK38/20-XL**

Needle roller bearing

Needle roller bearings NK, light series

X-life

Technical information

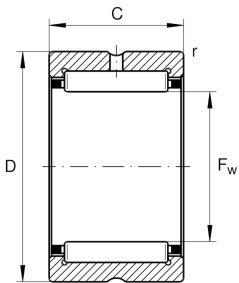

Your current product variant

Lubricant	Without	
Cage	Standard	
Cage feature	Standard	
Tolerance class	PN	Normal (DIN 620-2)

Main Dimensions & Performance Data

F_w	38 mm	Under roller diameter
D	48 mm	Outside diameter
C	20 mm	Width, outer ring
C_r	29.000 N	Basic dynamic load rating, radial
C_{0r}	45.000 N	Basic static load rating, radial
C_{ur}	8.100 N	Fatigue load limit, radial
n_G	12.000 1/min	Limiting speed
n_{gr}	7.200 1/min	Reference speed
$\approx m$	77,3 g	Weight

Dimensions

r_{min}	0,3 mm	Minimum chamfer dimension
-----------	--------	---------------------------



Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Additional information

G38X48X4	Sealing ring
SD38X48X4	Sealing ring 2

Characteristics

-  Radial load
-  Grease Lubrication
-  Oil Lubrication
-  Not sealed
-  Small design envelope