
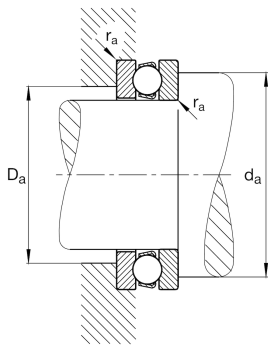


**FAG****51228**

Axial deep groove ball bearing

Axial deep groove ball bearing 512, single direction, steel sheet metal cage

Technical information

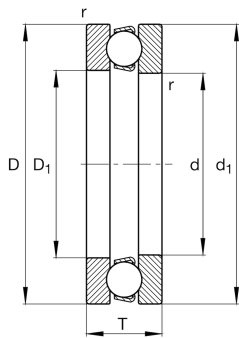

Your current product variant

Cage	JP	Steel sheet metal
Tolerance class	PN	Normal (ISO 492:2023)
Dimensional / heat stabilization	S0	Rings dimensional stabilized up to 150°

Main Dimensions & Performance Data

d	140 mm	Inner diameter shaft washer
D	200 mm	Outer diameter housing washer
T	46 mm	Height
C _a	191.000 N	Basic dynamic load rating, axial
C _{0a}	570.000 N	Basic static load rating, axial
C _{ua}	19.800 N	Fatigue load limit, axial
n _G	2.110 1/min	Limiting speed
n _{gr}	2.700 1/min	Reference speed
m	4,265 kg	Weight

Mounting dimensions

d _{a min}	176 mm	Minimum diameter shaft shoulder
D _{a max}	164 mm	Maximum diameter of housing shoulder
r _{a max}	1,5 mm	Maximum filled radius



Dimensions

r _{min}	1,5 mm	Minimum chamfer dimension
D ₁	143 mm	Inner diameter housing washer
d ₁	197 mm	Outer diameter shaft washer

Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	150 °C	Operating temperature max.

Calculation factors

A	1,9	Minimum load factor
---	-----	---------------------

Characteristics

	F _a	Axial load in one direction
		Grease Lubrication
		Oil Lubrication
		Not sealed