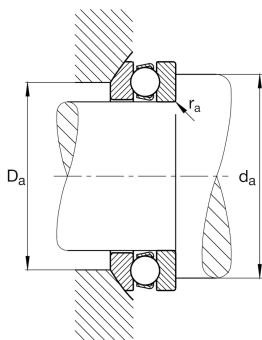
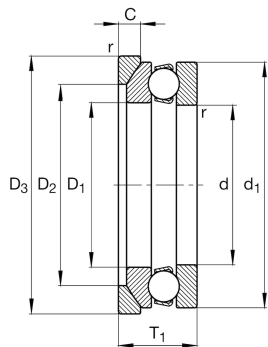
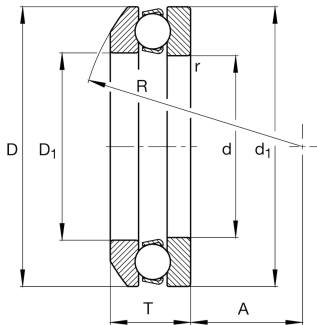
**FAG****53205** **Axial deep groove ball bearing**

Axial deep groove ball bearing 532, single direction, with spherical housing washer, steel sheet metal cage

Technical information**Your current product variant**


Cage	JP	Steel sheet metal
Tolerance class	PN	Normal (ISO 492:2023)
Dimensional / heat stabilization	S0	Rings dimensional stabilized up to 150°

Main Dimensions & Performance Data

d	25 mm	Inner diameter shaft washer
D	47 mm	Outer diameter housing washer
T	16,7 mm	Height
C _a	26.500 N	Basic dynamic load rating, axial
C _{0a}	50.000 N	Basic static load rating, axial
C _{ua}	2.280 N	Fatigue load limit, axial
n _G	7.500 1/min	Limiting speed
n _{gr}	9.800 1/min	Reference speed
≈m	0,119 kg	Weight

Mounting dimensions

d _{a min}	38 mm	Minimum diameter shaft shoulder
D _{a max}	36 mm	Maximum diameter of housing shoulder
r _{a max}	0,6 mm	Maximum filled radius

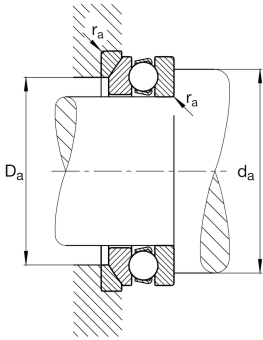

Dimensions

r _{min}	0,6 mm	Minimum chamfer dimension
D ₁	27 mm	Inner diameter housing washer
d ₁	47 mm	Outer diameter shaft washer
R	40 mm	Radius spherical housing washer
A	19 mm	Distance of the center point
T ₁	19 mm	Height with seat washer
D ₂	36 mm	Bore diameter seat washer
D ₃	50 mm	Outside diameter seat washer
C	5,5 mm	Height seat washer

Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	150 °C	Operating temperature max.

Calculation factors

A	0,013	Minimum load factor
---	-------	---------------------

Additional information

U205	Seat washer
------	-------------

Characteristics

	Axial load in one direction
	Grease Lubrication
	Oil Lubrication
	Not sealed
	Static angular error and misalignment