
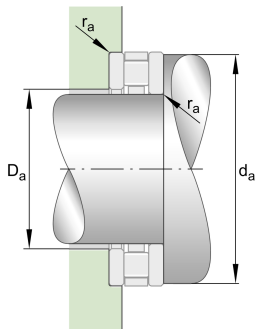


**81109-TV** [🔗](#)

Axial cylindrical roller bearing

Axial cylindrical roller bearings 811, single direction, comprising K811, GS, WS

Technical information

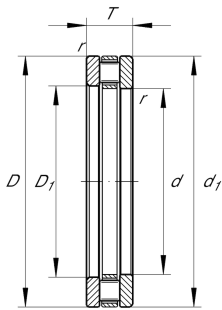

Your current product variant

Cage	TV	Plastic Cage made from PA66
------	----	-----------------------------

Main Dimensions & Performance Data

d	45 mm	Bore diameter
T	14 mm	Height
C _a	59.000 N	Basic dynamic load rating, axial
C _{0a}	163.000 N	Basic static load rating, axial
C _{ua}	16.300 N	Fatigue load limit, axial
n _G	5.200 1/min	Limiting speed
n _{gr}	1.970 1/min	Reference speed
D	65 mm	Outside diameter
m	131 g	Weight

Mounting dimensions

d _{a min}	63 mm	Minimum diameter shaft shoulder
D _{a max}	47 mm	Maximum diameter of housing shoulder
r _{a max}	0,6 mm	Maximum recess radius



Dimensions

D ₁	47 mm	Bore diameter housing washer
d ₁	65 mm	Rip diameter shaft washer
r _{min}	0,6 mm	Minimum chamfer dimension

Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Additional information

K81109-TV	Axial roller and cage assembly
GS81109	Housing Washer
WS81109	Shaft washer
LS4565	Track Washer

Characteristics

 F _a	Axial load in one direction
	Grease Lubrication
	Oil Lubrication
	Not sealed