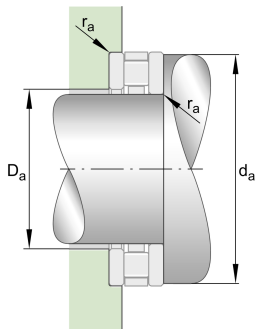
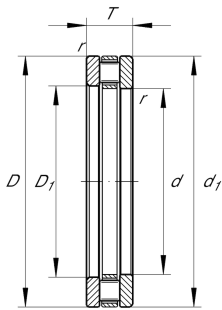


**81112-TV** **Axial cylindrical roller bearing**

Axial cylindrical roller bearings 811, single direction, comprising K811, GS, WS

Technical information**Your current product variant**

Cage	TV	Plastic Cage made from PA66
------	----	-----------------------------

Main Dimensions & Performance Data

d	60 mm	Bore diameter
T	17 mm	Height
C _a	103.000 N	Basic dynamic load rating, axial
C _{0a}	315.000 N	Basic static load rating, axial
C _{ua}	32.500 N	Fatigue load limit, axial
n _G	3.950 1/min	Limiting speed
n _{gr}	1.360 1/min	Reference speed
D	85 mm	Outside diameter
m	269,4 g	Weight

Mounting dimensions

d _{a min}	82 mm	Minimum diameter shaft shoulder
D _{a max}	62 mm	Maximum diameter of housing shoulder
r _{a max}	1 mm	Maximum recess radius



Dimensions

D ₁	62 mm	Bore diameter housing washer
d ₁	85 mm	Rip diameter shaft washer
r _{min}	1 mm	Minimum chamfer dimension

Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.

Additional information

K81112-TV	Axial roller and cage assembly
GS81112	Housing Washer
WS81112	Shaft washer
LS6085	Track Washer

Characteristics

 F _a	Axial load in one direction
	Grease Lubrication
	Oil Lubrication
	Not sealed