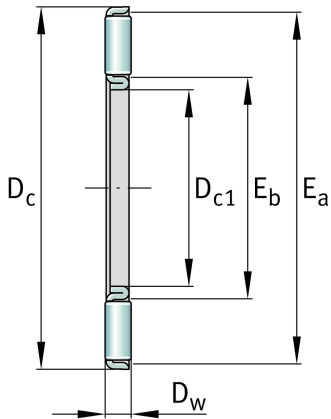
**AXK100135-A/0-10** [🔗](#)**Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	100 mm	Bore diameter cage
D_c	135 mm	Outside diameter
D_w	4 mm	Rolling element diameter
E_a	133 mm	Raceway dimension
E_b	105 mm	Raceway dimension
c_a	91.000 N	Basic dynamic load rating, axial
c_{0a}	560.000 N	Basic static load rating, axial
c_{ua}	59.000 N	Fatigue load limit, axial
n_G	2.420 1/min	Limiting speed
n_{gr}	970 1/min	Reference speed
$\approx m$	97,5 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS100135

Axial bearing washer