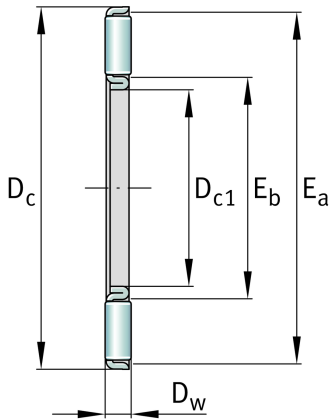
**AXK1024-A/0-10** [🔗](#)**Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	10 mm	Bore diameter cage
D_c	24 mm	Outside diameter
D_w	2 mm	Rolling element diameter
E_a	23 mm	Raceway dimension
E_b	12 mm	Raceway dimension
c_a	9.200 N	Basic dynamic load rating, axial
c_{0a}	25.500 N	Basic static load rating, axial
c_{ua}	2.550 N	Fatigue load limit, axial
n_G	16.900 1/min	Limiting speed
n_{gr}	7.400 1/min	Reference speed
$\approx m$	3,107 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS1024

Axial bearing washer