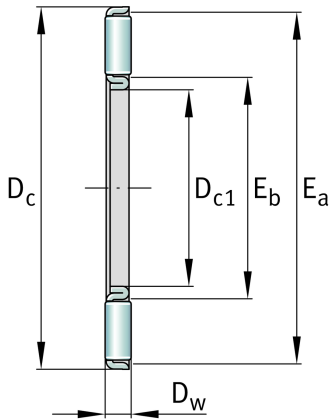
**AXK1226-A/0-10** [🔗](#)**Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	12 mm	Bore diameter cage
D_c	26 mm	Outside diameter
D_w	2 mm	Rolling element diameter
E_a	25 mm	Raceway dimension
E_b	14 mm	Raceway dimension
c_a	9.900 N	Basic dynamic load rating, axial
c_{0a}	29.000 N	Basic static load rating, axial
c_{ua}	2.950 N	Fatigue load limit, axial
n_G	15.200 1/min	Limiting speed
n_{gr}	6.500 1/min	Reference speed
$\approx m$	3,488 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS1226

Axial bearing washer