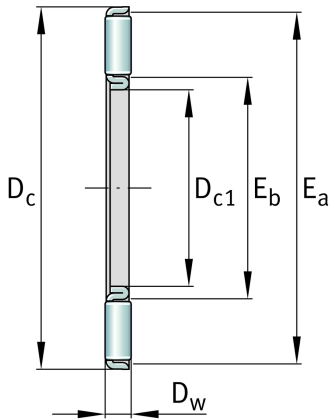
**AXK130170-A/0-10** [🔗](#)**Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	130 mm	Bore diameter cage
D_c	170 mm	Outside diameter
D_w	5 mm	Rolling element diameter
E_a	167 mm	Raceway dimension
E_b	136 mm	Raceway dimension
c_a	134.000 N	Basic dynamic load rating, axial
c_{0a}	840.000 N	Basic static load rating, axial
c_{ua}	77.000 N	Fatigue load limit, axial
n_G	1.920 1/min	Limiting speed
n_{gr}	760 1/min	Reference speed
$\approx m$	189,3 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS130170

Axial bearing washer