
**AXK2035-A/0-10** [🔗](#)

Axial needle roller and cage assembly

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information

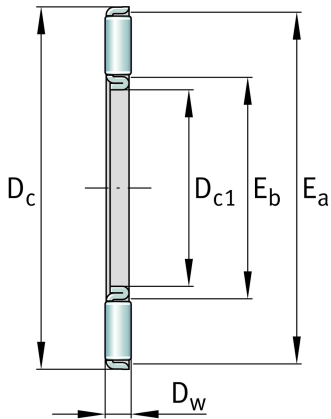

Main Dimensions & Performance Data

D_{c1}	20 mm	Bore diameter cage
D_c	35 mm	Outside diameter
D_w	2 mm	Rolling element diameter
E_a	34 mm	Raceway dimension
E_b	22 mm	Raceway dimension
c_a	13.100 N	Basic dynamic load rating, axial
c_{0a}	46.500 N	Basic static load rating, axial
c_{ua}	4.800 N	Fatigue load limit, axial
n_G	10.500 1/min	Limiting speed
n_{gr}	4.350 1/min	Reference speed
$\approx m$	5,4 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS2035

Axial bearing washer