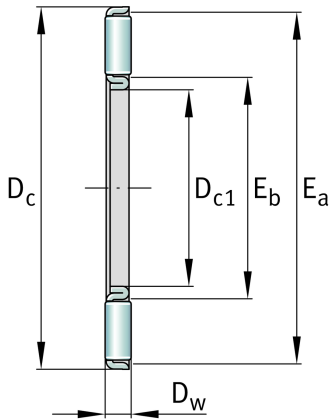
**AXK6590-A/0-10** [🔗](#)**Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	65 mm	Bore diameter cage
D_c	90 mm	Outside diameter
D_w	3 mm	Rolling element diameter
E_a	88 mm	Raceway dimension
E_b	70 mm	Raceway dimension
c_a	47.000 N	Basic dynamic load rating, axial
c_{0a}	255.000 N	Basic static load rating, axial
c_{ua}	29.000 N	Fatigue load limit, axial
n_G	3.700 1/min	Limiting speed
n_{gr}	1.470 1/min	Reference speed
$\approx m$	35,5 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS6590

Axial bearing washer