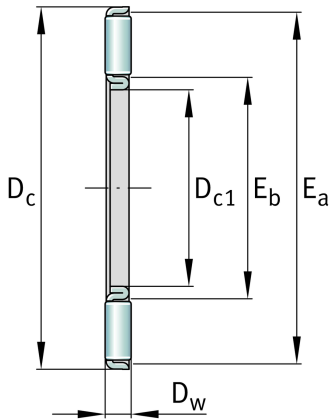
**AXK90120-A/0-10** **Axial needle roller and cage assembly**

Axial needle roller and cage assemblies,
single direction, to DIN 5405-2

Technical information**Main Dimensions & Performance Data**

D_{c1}	90 mm	Bore diameter cage
D_c	120 mm	Outside diameter
D_w	4 mm	Rolling element diameter
E_a	118 mm	Raceway dimension
E_b	94 mm	Raceway dimension
c_a	73.000 N	Basic dynamic load rating, axial
c_{0a}	405.000 N	Basic static load rating, axial
c_{ua}	45.500 N	Fatigue load limit, axial
n_G	2.750 1/min	Limiting speed
n_{gr}	1.120 1/min	Reference speed
$\approx m$	74,45 g	Weight

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Additional information

AS90120

Axial bearing washer