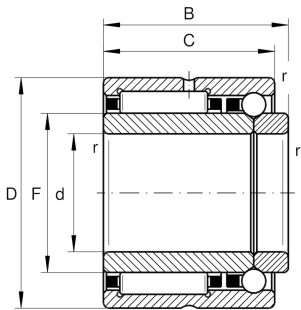
**NKIB5902-XL**

Needle roller/angular contact ball bearing

Needle roller/angular contact ball bearings
NKIB, double direction axial component**X-life**

Technical information

**Main Dimensions & Performance Data**

d	15 mm	Bore diameter
D	28 mm	Outside diameter
B	20 mm	Width
C _r	12.000 N	Basic dynamic load rating, radial
C _{0r}	13.600 N	Basic static load rating, radial
C _a	2.900 N	Basic dynamic load rating, axial
C _{0a}	4.200 N	Basic static load rating, axial
C _{ur}	2.470 N	Fatigue load limit, radial
C _{ua}	191 N	Fatigue load limit, axial
n _G	21.600 1/min	Limiting speed
n _{gr}	17.000 1/min	Reference speed
≈m	50,89 g	Weight

Dimensions

F	20 mm	Raceway diameter inner ring
C	18 mm	Width, outer ring
r _{min}	0,3 mm	Minimum chamfer dimension



Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.

Characteristics

-  F_r Radial load
-  F_a Axial load in one direction
-  F_a Axial load in two directions
-  Grease Lubrication
-  Oil Lubrication
-  Not sealed
-  Small design envelope