


X-life

LR5201-2Z-TVH-XL

Yoke type track roller

Yoke type track rollers LR52...-2Z-TVH-XL, double row self-retaining angular contact ball bearings with particularly thick-walled outer ring, ball and cage assembly and an inner ring, axial guidance of outer ring is provided by the balls, lubrication hole in inner ring on request, sealing shield on both sides, cage made from glass fibre reinforced polyamide, X-life design

Technical information

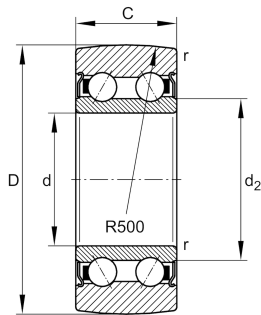

Your current product variant

Type of Seal	2Z	Sealing shield on both sides
Outer ring profile	R500	R500
Relubrication facility	Without	Without
Cage	TVH	Solid cage made of glass-fiber reinforced polyamid PA66

Main Dimensions & Performance Data

D	35 mm	Outside diameter
d	12 mm	Bore diameter
C	15,9 mm	Height
C_{rw}	8.800 N	Effective dynamic load rating, radial
C_{0rw}	6.100 N	Effective static load rating, radial
C_{urw}	315 N	Effective fatigue limit load, radial
n_{DG}	8.100 1/min	Speed on permanent grease lubrication
F_{rper}	4.800 N	Permissible dynamic load, radial
$\approx m$	0,08 kg	Weight



Dimensions

d 2	19,1 mm	Diameter of thrust washer
r min	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile