

**PSHEY25-XL-N** [↗](#)

Plummer block housing unit

Plummer block housing units PSHEY, cast iron housing, radial insert ball bearing with grub screws in inner ring, P seals

X-life

Technical information

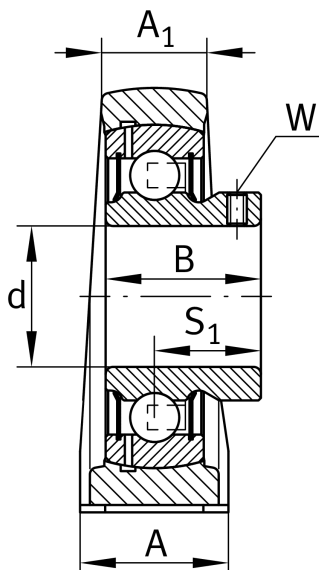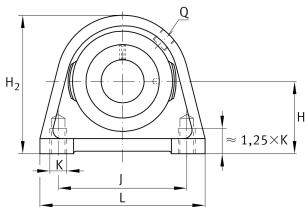

Your current product variant

Groove	N	Cast iron housing with undercut slot for end caps
Material	GG	Grey cast iron

Main Dimensions & Performance Data

d	25 mm	Bore diameter
L	70 mm	Length total
H 2	70 mm	Height
≈m	0,51 kg	Weight

Mounting dimensions

J	50,8 mm	Distance fixing bore
K	M10	Thread fixing bore

Dimensions

H	36,5 mm	Distance shaft axis
A	36 mm	Width (base)
A 1	21 mm	Width (head)
Q	M6	Connection thread for lubrication
S 1	19,5 mm	Distance of raceway to locking collar



Additional information

SHE05	Housing
GAY25-XL-NPP-B	Bearing designation
KASK05	Protecting cap

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.