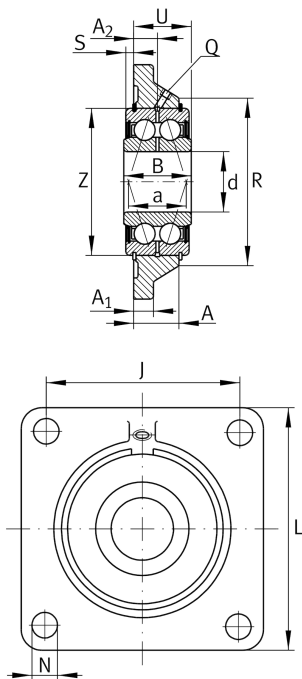


**PCCJ25** **Flanged housing unit**

Housing units PCCJ, four-bolt flanged housing units, cast iron, double row angular contact ball bearing, P seals

Technical information**Your current product variant**

Material	GG	Grey cast iron
----------	----	----------------

Main Dimensions & Performance Data

d	25 mm	Bore diameter
L	95 mm	Flange width
U	26,7 mm	Total height unit
C _r	21.600 N	Basic dynamic load rating, radial
C _{0r}	14.900 N	Basic static load rating, radial
C _{ur}	760 N	Fatigue load limit, radial
≈m	0,89 kg	Weight

Mounting dimensions

J	70 mm	Distance fixing bore
N	11,5 mm	Fixing bore
n	4	Number of screwing holes

Dimensions

A	22,1 mm	Height housing
A ₁	12 mm	Thickness of flange
A ₂	11,7 mm	Distance raceway
B	30 mm	Width
Q	M6	Connection thread for lubrication



View product details on medias

30.07.2026, 09:44:14 UTC

SCHAEFFLER

Additional information

1	Number of housings
CCJ05	Housing
G5205-2RS-N	Bearing designation