


IR35X40X20-EGS [↗](#)

Inner ring

Inner ring IR...-EGS, cylindrical

Technical information

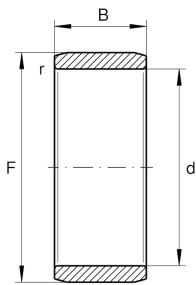

Your current product variant

Lubrication hole	Without	
Rail connector	EGS	Sureface ground free from spiral marks

Main Dimensions & Performance Data

d	35 mm	Bore diameter
F	40 mm	Raceway diameter inner ring
B	20 mm	Width
r _{min}	0,3 mm	Minimum chamfer dimension
≈m	44,61 g	Weight