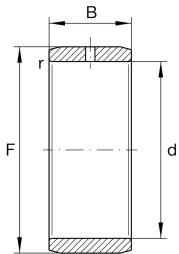
**IR25X30X16-IS1-XL**

## Inner ring

Inner rings IR...IS1, precision machined, with lubrication hole, to DIN 620

**X-life**

## Technical information

**Your current product variant**

|                  |         |      |
|------------------|---------|------|
| Lubrication hole | IS1     | With |
| Rail connector   | Without |      |

**Main Dimensions & Performance Data**

|                  |           |                                  |
|------------------|-----------|----------------------------------|
| d                | 25 mm     | Bore diameter                    |
| F                | 30 mm     | Raceway diameter inner ring      |
| B                | 16 mm     | Width                            |
|                  | 0 mm      | Raceway diameter upper tolerance |
|                  | -0,012 mm | Raceway diameter lower tolerance |
| r <sub>min</sub> | 0,3 mm    | Minimum chamfer dimension        |
| ≈m               | 23,9 g    | Weight                           |

**Mounting dimensions**

|   |                             |
|---|-----------------------------|
| 1 | Number of lubrication holes |
|---|-----------------------------|