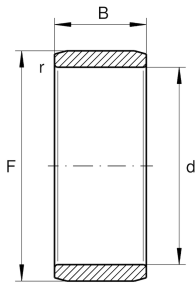
**IR100X110X40-XL**

Inner ring

Inner ring IR...XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	100 mm	Bore diameter
F	110 mm	Raceway diameter inner ring
B	40 mm	Width
	-0,014 mm	Raceway diameter upper tolerance
	-0,027 mm	Raceway diameter lower tolerance
r min	1,1 mm	Minimum chamfer dimension
≈m	0,505 kg	Weight