


IR110X125X40-XL [↗](#)

Inner ring

Inner ring IR...XL, cylindrical

X-life

Technical information

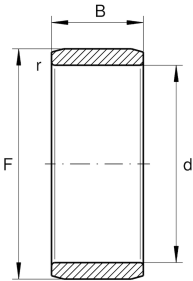

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	110 mm	Bore diameter
F	125 mm	Raceway diameter inner ring
B	40 mm	Width
	-0,007 mm	Raceway diameter upper tolerance
	-0,022 mm	Raceway diameter lower tolerance
r min	1,1 mm	Minimum chamfer dimension
≈m	849 g	Weight