


IR15X20X13-XL [↗](#)

Inner ring

Inner ring IR...XL, cylindrical

X-life

Technical information

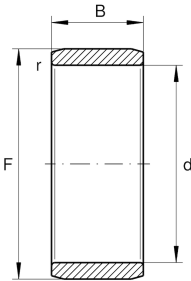

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	15 mm	Bore diameter
F	20 mm	Raceway diameter inner ring
B	13 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,012 mm	Raceway diameter lower tolerance
r min	0,3 mm	Minimum chamfer dimension
≈m	13,27 g	Weight