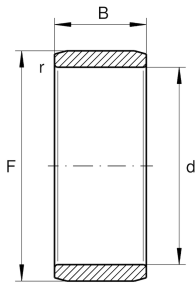
**IR17X20X20-XL** [🔗](#)

Inner ring

Inner ring IR...-XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	17 mm	Bore diameter
F	20 mm	Raceway diameter inner ring
B	20 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,012 mm	Raceway diameter lower tolerance
r min	0,3 mm	Minimum chamfer dimension
≈m	13,36 g	Weight