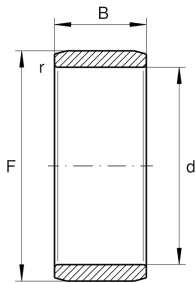
**IR22X28X17-XL** [🔗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	22 mm	Bore diameter
F	28 mm	Raceway diameter inner ring
B	17 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,012 mm	Raceway diameter lower tolerance
r min	0,3 mm	Minimum chamfer dimension
≈m	29,8 g	Weight