


IR35X40X20,5-XL [🔗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

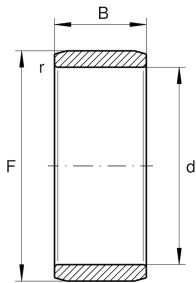

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	35 mm	Bore diameter
F	40 mm	Raceway diameter inner ring
B	20,5 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,009 mm	Raceway diameter lower tolerance
r min	0,3 mm	Minimum chamfer dimension
≈m	46 g	Weight