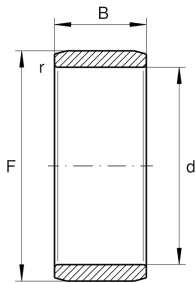
**IR35X40X30-XL** [🔗](#)

Inner ring

Inner ring IR..-XL, cylindrical

**X-life**

## Technical information

**Your current product variant**

|                  |         |
|------------------|---------|
| Lubrication hole | Without |
| Rail connector   | Without |

**Main Dimensions & Performance Data**

|       |           |                                  |
|-------|-----------|----------------------------------|
| d     | 35 mm     | Bore diameter                    |
| F     | 40 mm     | Raceway diameter inner ring      |
| B     | 30 mm     | Width                            |
|       | 0 mm      | Raceway diameter upper tolerance |
|       | -0,009 mm | Raceway diameter lower tolerance |
| r min | 0,3 mm    | Minimum chamfer dimension        |
| ≈m    | 67,49 g   | Weight                           |