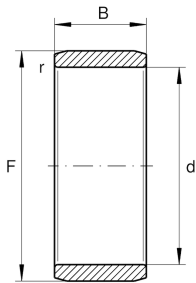
**IR40X48X22-XL**

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	40 mm	Bore diameter
F	48 mm	Raceway diameter inner ring
B	22 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,009 mm	Raceway diameter lower tolerance
r min	0,6 mm	Minimum chamfer dimension
≈m	91,8 g	Weight