


IR45X50X35-XL [↗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

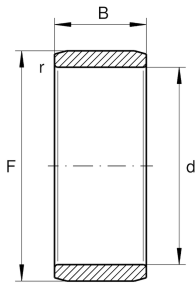

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	45 mm	Bore diameter
F	50 mm	Raceway diameter inner ring
B	35 mm	Width
	-0,005 mm	Raceway diameter upper tolerance
	-0,019 mm	Raceway diameter lower tolerance
r min	0,6 mm	Minimum chamfer dimension
≈m	0,099 kg	Weight