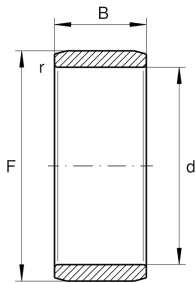
**IR50X58X22-XL** [🔗](#)

Inner ring

Inner ring IR...XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	50 mm	Bore diameter
F	58 mm	Raceway diameter inner ring
B	22 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,011 mm	Raceway diameter lower tolerance
r min	0,6 mm	Minimum chamfer dimension
≈m	0,113 kg	Weight