


IR50X58X40-XL [↗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

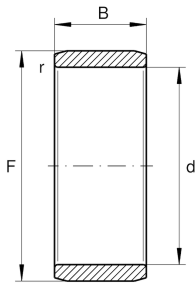

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	50 mm	Bore diameter
F	58 mm	Raceway diameter inner ring
B	40 mm	Width
	0 mm	Raceway diameter upper tolerance
	-0,011 mm	Raceway diameter lower tolerance
r min	0,6 mm	Minimum chamfer dimension
m	0,208 kg	Weight