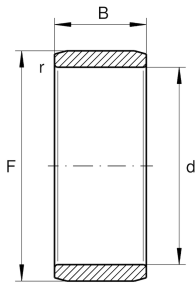
**IR55X63X25-XL** [🔗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

**Your current product variant**

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	55 mm	Bore diameter
F	63 mm	Raceway diameter inner ring
B	25 mm	Width
	-0,01 mm	Raceway diameter upper tolerance
	-0,021 mm	Raceway diameter lower tolerance
r min	1 mm	Minimum chamfer dimension
≈m	0,14 kg	Weight