


IR70X80X30-XL [🔗](#)

Inner ring

Inner ring IR..-XL, cylindrical

X-life

Technical information

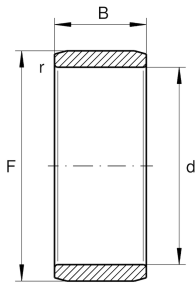

Your current product variant

Lubrication hole	Without
Rail connector	Without

Main Dimensions & Performance Data

d	70 mm	Bore diameter
F	80 mm	Raceway diameter inner ring
B	30 mm	Width
	-0,01 mm	Raceway diameter upper tolerance
	-0,026 mm	Raceway diameter lower tolerance
r min	1 mm	Minimum chamfer dimension
≈m	0,268 kg	Weight