


FAG

KM19

Locknut

Locknuts KM, main dimensions to DIN 981

Technical information

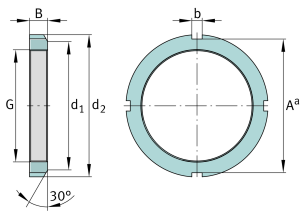

Main Dimensions & Performance Data

G	M95x2	Thread
d 2	125 mm	Outside diameter
B	17 mm	Width
≈m	0,673 kg	Weight

Mounting dimensions

d 1	113 mm	Chamfer diameter
b	10 mm	Width retaining slot
A^a	117 mm	Groove base distance

Additional information

F	270.000 N	Axial load capacity, static
	MB19	Fuse
	30 °	Chamfer angle