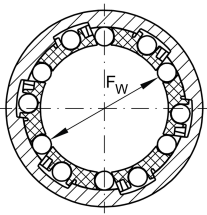
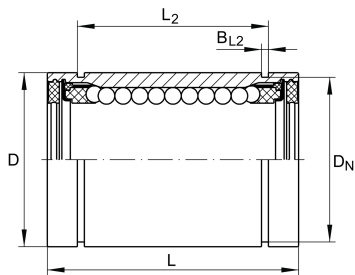
**KB12** **Linear Ball Bearing**

Linear ball bearings KB..., machined range,
corrosion-resistant design possible

Technical information**Your current product variant**

Size code 12

Main Dimensions & Performance Data

F _W	12 mm	Bore diameter
	+0,008/0	Tolerance
D	22 mm	Outside diameter
	h5	Tolerance
L	32 mm	Length
	h12	Tolerance
C _{min}	540 N	Load capacity dyn.
C _{0 min}	385 N	Load capacity stat.
C _{max}	640 N	Load capacity dyn.
C _{0 max}	570 N	Load capacity stat.
≈m	36,54 g	Weight

Mounting dimensions

L ₂	22,6 mm	
	H13	Tolerance
B _{L2}	1,3 mm	
D _N	21 mm	
N ₂	1,5 mm	
	5	Number of rows balls